



SKU
WD410-24X24


Job Name:
Mark:
Submitted By:
Date: 01/16/2021

Backdraft damper, vertical or horizontal mount, Model WD-410, 24 In Sq, No Flange, Performance up to 2,500 ft/min



The WD-410 series are non-motorized backdraft dampers which may be mounted either vertically for intake air or mounted horizontally to allow vertical airflow down and prevent reverse airflow. The dampers are opened by air pressure differential and closed by springs.

- Width and height furnished approximately 0.125 in. under size

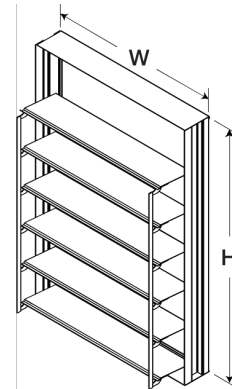

H	W
23.875 in	23.875 in

Performance Characteristics

No Fan Curve Available.

Construction Features

Frame Material	Galvanized Steel
Frame Gauge	18
Frame Type	No Flange
Blade Material	Roll formed aluminum
Blade Gauge	0.025

California Residents

⚠ WARNING

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit www.P65Warnings.ca.gov