




SKU  
IC-18-B4-J1-QD

Nombre del Proyecto:  
Marca:  
Enviado por:  
Fecha: 10/22/2020

## Non-oscillating Air Circulator, Model IC-18, 1/4HP, 115V, 1Ph, 2900-4500 CFM

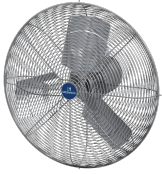


Model IC, non-oscillating circulator fans are designed for air movement in humid and demanding applications. Units are ideal for spot cooling and recirculating air in factories, warehouses, manufacturing facilities and garages. Mounting accessory sold separately.

- Totally enclosed motor
- Preassembled
- OSHA-compliant zinc plated wire guard

### Certifications

UL/cUL 507

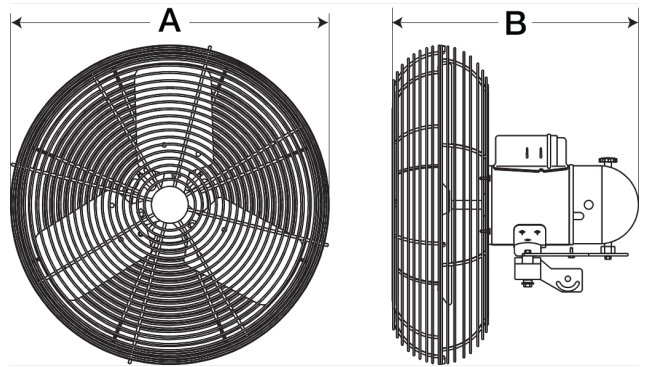

A	B
21 in	12.75 in

### Características de funcionamiento

No hay curva del ventilador disponible.

### Características de Construcción

Drive Type	Direct Drive
Impeller Type	Propeller
Impeller Material	Aluminum
Includes	Mounting hardware Power cord with 3-prong plug
Max Inlet Temp	104 °F
Certifications	UL/cUL 507
Required Accessory	Mounting accessory

### Información del motor

Service Factor	1
Phase	1
Voltage	115
HP	1/4
Hertz	60
Motor Enclosure	Totally Enclosed Air Over
RPM	1200
Motor Insulation	B
Thermal Protection	Auto
Nominal Efficiency	64
NEMA Frame Size	48

### Rendimiento de Aire y Sonido

HP Motor	BHP Max	Max Fan RPM	Min Fan RPM	Ps (in. wg)
1/4	0.00	750	0	PCM
				Sones
1/4	0.00	1075	0	PCM
				Sones

## California Residents

 **WARNING**

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)