




SKU
IC-20-B4-J1-QD

Job Name:
Mark:
Submitted By:
Date: 01/17/2020

Non-oscillating Air Circulator, Model IC-20, 1/4HP, 115V, 1Ph, 3055-4700 CFM

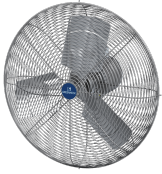


Model IC, non-oscillating circulator fans are designed for air movement in humid and demanding applications. Units are ideal for spot cooling and recirculating air in factories, warehouses, manufacturing facilities and garages. Mounting accessory sold separately.

- Totally enclosed motor
- Preassembled
- OSHA-compliant zinc plated wire guard

Certifications

UL/cUL 507

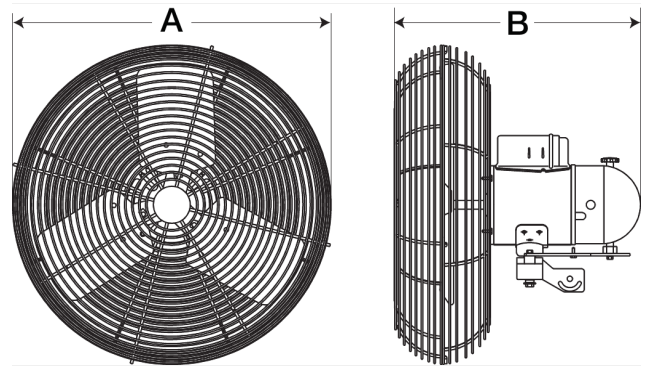

A	B
23 in	12.75 in

Performance Characteristics

No Fan Curve Available.

Construction Features

Drive Type	Direct Drive
Impeller Type	Propeller
Impeller Material	Aluminum
Includes	Mounting hardware Power cord with 3-prong plug
Max Inlet Temp	104 °F
Certifications	UL/cUL 507
Required Accessory	Mounting accessory

Motor Information

Service Factor	1
Phase	1
Voltage	115
HP	1/4
Hertz	60
Motor Enclosure	Totally Enclosed Air Over
RPM	1200
Motor Insulation	B
Thermal Protection	Auto
Nominal Efficiency	64
NEMA Frame Size	48

Air and Sound Performance

Motor HP	Max BHP	Max Fan RPM	Min Fan RPM	Ps (in. wg)
1/4	0.00	750	0	CFM
				Sones
1/4	0.00	1075	0	CFM
				Sones