



SKU  
DS-3-16-70LV-X-QD

Nombre del Proyecto:  
Marca:  
Enviado por:  
Fecha: 10/30/2020

# HVLS Fan, Model DS-3, Low Voltage 208/230/277v, 16 ft diameter, 3-blade, Fan Performance up to 106,300 CFM




Model DS-3 is a three-blade, direct drive HVLS fan designed for commercial or industrial spaces with medium to high ceilings. These economical fans are the ideal balance between cost and performance, making them a smart choice for budget-conscious building owners. Plus, with a lighter weight than comparable HVLS fans, the DS-3 is a breeze to install in any building.

- Plug-and-Play
- Safety Retention Cables & Guy Wires
- Impact & Over Speed Detection
- Electrical Safety Systems
- 10-year Warranty


### Certifications

AMCA Circulating Fan Performance  
CSA Certified  
UL/cUL 507

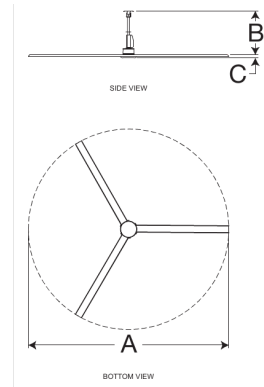

A	B	C
192 in	42 in	3 in

### Características de funcionamiento

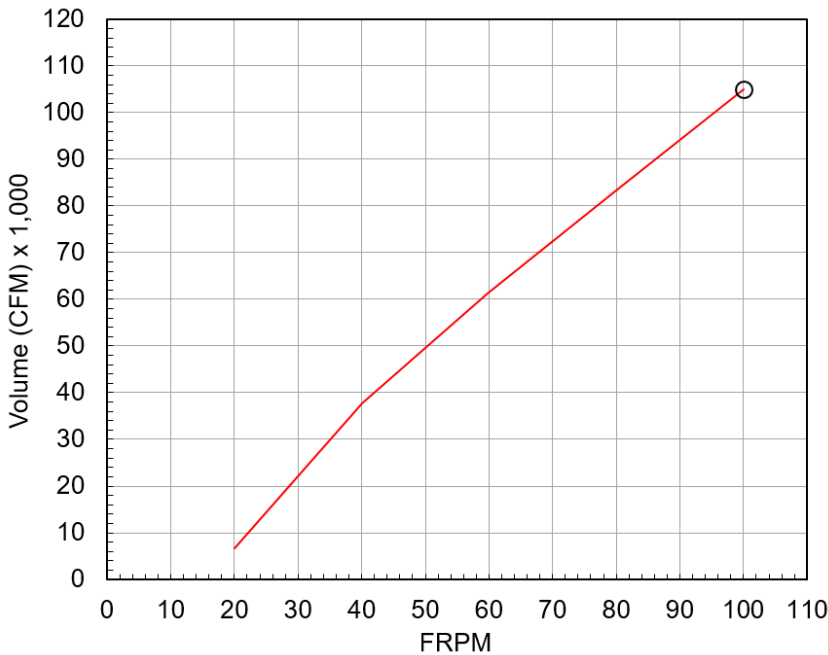

### Características de Construcción

Drive Type	Direct Drive
Impeller Type	Propeller/Axial
Impeller Material	Aluminum
Certifications	AMCA Circulating Fan Performance CSA Certified UL/cUL 507
Speed Controllable	Yes

### Información del motor

Phase	1 3
Voltage	208-230 277
HP	3/4

### California Residents

#### ⚠ WARNING

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)