



SKU
DC-5-12-13LV-X-QD


Nombre del Proyecto:
Marca:
Enviado por:
Fecha: 02/27/2021

HVLS Fan, Model DC-5, Low Voltage 115/208-230v, 12 ft diameter, 5-blade, Fan Performance up to 50,000 CFM



Model DC-5 is an aesthetic five-blade, direct drive design for use in commercial spaces with low to medium height ceilings. Combined with its sleek design, the DC-5 provides comfortable air movement in office spaces, restaurants, fitness centers, and more. These fans are effortless to install with a total weight less than one hundred pounds, the lightest among comparable HVLS fans.

- Plug-and-Play
- Galvanized Steel Safety Cable
- Electrical Safety Systems
- Impact & Over Speed Detection
- 10-year Warranty

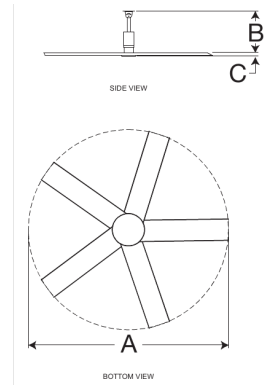


A	B	C
144 in	24 in	2 in

Certifications

AMCA Circulating Fan Performance
CSA Certified
UL/cUL 507

Características de funcionamiento

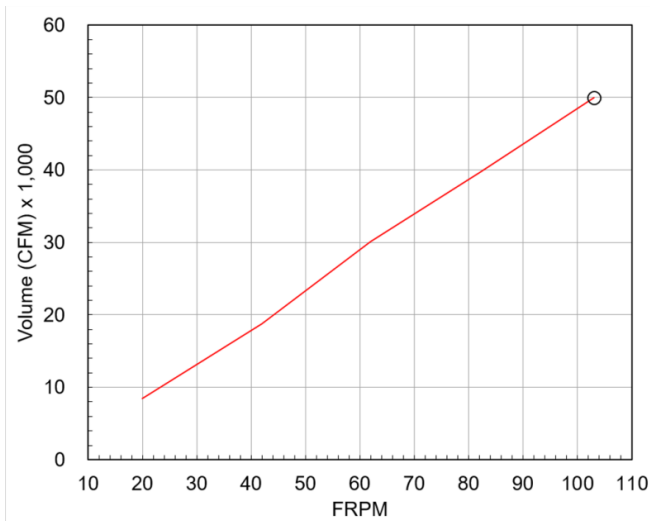

Características de Construcción

Drive Type	Direct Drive
Impeller Type	Propeller/Axial
Impeller Material	Aluminum
Certifications	AMCA Circulating Fan Performance CSA Certified UL/cUL 507
Speed Controllable	Yes

Información del motor

Phase	1
Voltage	115 208-230
HP	1/4

California Residents

⚠ WARNING

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit www.P65Warnings.ca.gov