




SKU
RBDR50-6

Nombre del Proyecto:
Marca:
Enviado por:
Fecha: 02/27/2021

Round Remote Balancing Damper, 6 In Diameter

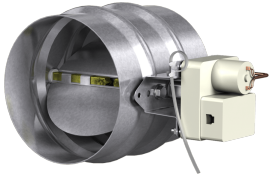

Remote balancing dampers are ideal for applications where access is difficult for manually adjusting airflow balance. The “EZ Balance” remote control operates the damper motor by connecting an RJ11 connector mounted on the wall, ceiling, or diffuser.

- EZ balance handheld remote, equipped with 9-volt power supply, operates the damper actuator (sold separately)
- Cables, wall plates and connectors available as accessories
- Factory-mounted actuator
- 1 in. wg. pressure differential
- Maximum velocity of 2,000 fpm
- Tested in accordance with AMCA Standard 500-D

Características de funcionamiento

No hay curva del ventilador disponible.

Características de Construcción

Frame Material	Galvanized Steel
Blade Material	Galvanized Steel

California Residents

 **WARNING**

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit www.P65Warnings.ca.gov