



SKU
DS-3-20-70HV-X-QD

Job Name:
Mark:
Submitted By:
Date: 10/22/2020

HVLS Fan, Model DS-3, High Voltage 460v, 20 ft diameter, 3-blade, Fan Performance up to 144,500 CFM




Model DS-3 is a three-blade, direct drive HVLS fan designed for commercial or industrial spaces with medium to high ceilings. These economical fans are the ideal balance between cost and performance, making them a smart choice for budget-conscious building owners. Plus, with a lighter weight than comparable HVLS fans, the DS-3 is a breeze to install in any building.

- Plug-and-Play
- Safety Retention Cables & Guy Wires
- Impact & Over Speed Detection
- Electrical Safety Systems
- 10-year Warranty


Certifications

AMCA Circulating Fan Performance
CSA Certified
UL/cUL 507

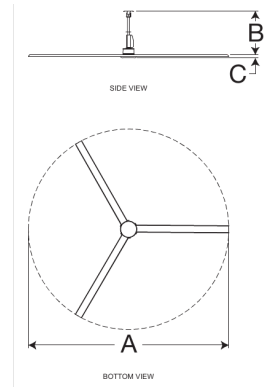

A	B	C
240 in	42 in	3 in

Performance Characteristics

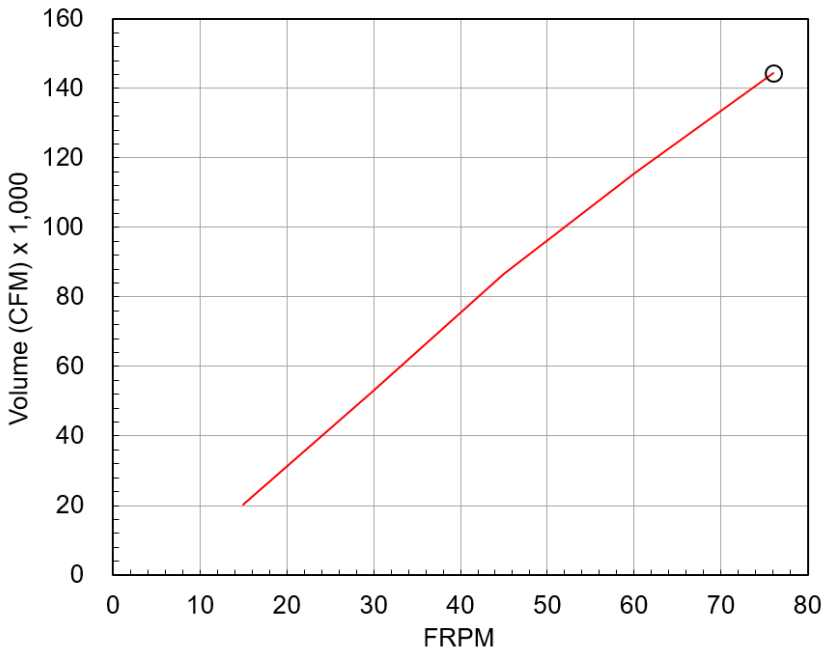

Construction Features

Drive Type	Direct Drive
Impeller Type	Propeller/Axial
Impeller Material	Aluminum
Certifications	AMCA Circulating Fan Performance CSA Certified UL/cUL 507
Speed Controllable	Yes

Motor Information

Phase	3
Voltage	460
HP	3/4

California Residents

⚠ WARNING

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit www.P65Warnings.ca.gov