



SKU
CSP-A700-VG-QD


Job Name:
Mark:
Submitted By:
Date: 10/22/2020

Inline Cabinet Fan, Variable Speed, Model CSP-A700-VG, Vari-Green EC motor, 115V/208-230/277v, 1 Ph, 67-895 CFM



Model CSP inline fans are high performance fans designed for exhaust, supply or return air applications where low sound level are required. Units feature an insulated, galvanized steel housing with a forward-curved wheel and an energy efficient, adjustable Vari-Green EC motor.

- Acoustic insulation absorbs sound for quiet operation
- Vertical electrical access to eliminate drilling holes
- Large electrical junction box for easy wiring
- Adjustable mounting brackets for multiple installation conditions
- Embossed, galvanized steel housing for rigidity
- Speed controllable motor
- Easy access to internal components through access panels

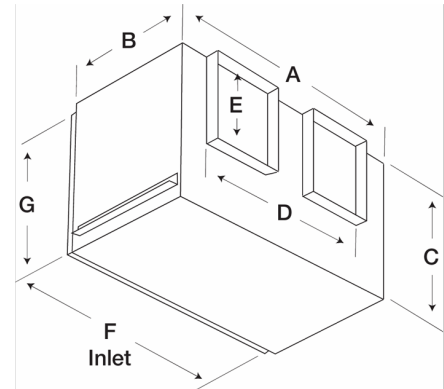

A	B	C	D	E	F	G
23.625 in	11.625 in	11.625 in	19.5 in	8 in	22.625 in	10.5 in

Certifications

AMCA Air
UL/cUL 507

Performance Characteristics

No Fan Curve Available.

Construction Features

Drive Type	Direct Drive
Impeller Type	Centrifugal Wheel
Impeller Material	Polypropylene
Housing Material	Galvanized Steel
Includes	Access Panel Backdraft damper Mounting brackets
Certifications	AMCA Air UL/cUL 507
Speed Controllable	Yes

California Residents

⚠ WARNING

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit www.P65Warnings.ca.gov