




SKU  
ICO-20-B4-J1-QD

Job Name:  
Mark:  
Submitted By:  
Date: 01/24/2021

## Oscillating Air Circulator, Model ICO-20, 1/4HP, 115V, 1Ph, 3055-4700 CFM

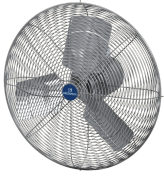


Model ICO, oscillating circulator fans are designed for air movement in humid and demanding applications. Units are ideal for spot cooling and recirculating air in factories, warehouses, manufacturing facilities and garages. Units sweep through 45° or 90° arc. Mounting accessory sold separately.

- Totally enclosed motor
- Preassembled
- OSHA-compliant zinc plated wire guard
- Circulator can sweep through 45° or 90° arc

### Certifications

UL/cUL 507

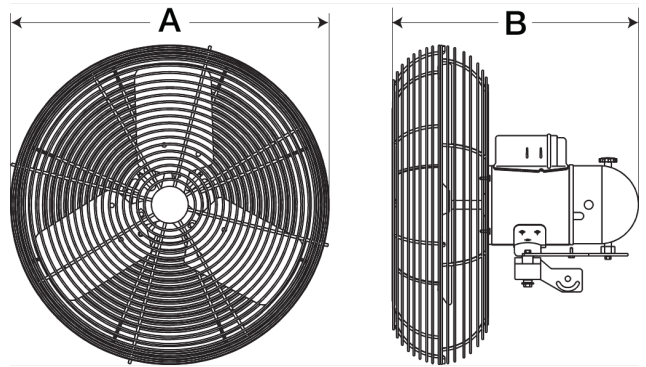

A	B
23 in	17.75 in

### Performance Characteristics

No Fan Curve Available.

### Construction Features

Drive Type	Direct Drive
Impeller Type	Propeller
Impeller Material	Aluminum
Includes	Mounting hardware Power cord with 3-prong plug
Max Inlet Temp	104 °F
Certifications	UL/cUL 507
Required Accessory	Mounting accessory

### Motor Information

Service Factor	1
Phase	1
Voltage	115
HP	1/4
Hertz	60
Motor Enclosure	Totally Enclosed Air Over
RPM	1200
Motor Insulation	B
Thermal Protection	No
Nominal Efficiency	60

### Air and Sound Performance

Motor HP	Max BHP	Max Fan RPM	Min Fan RPM	Ps (in. wg)
1/4	0.00	750	0	CFM
				Sones
1/4	0.00	1075	0	CFM
				Sones

## California Residents

 **WARNING**

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)