




SKU
SP-A110-QD

Nombre del Proyecto:
Marca:
Enviado por:
Fecha: 02/25/2020

Bathroom Exhaust Fan, Model SP-A110, 115V, 1Ph, 98-130 CFM



- Industry leading low sound levels
- ENERGY STAR rated
- Acoustic insulation absorbs sound ensuring quiet operation
- Spring loaded aluminum backdraft damper eliminates rattling
- External electrical access reduces installation time
- Speed controllable
- Designer grille included

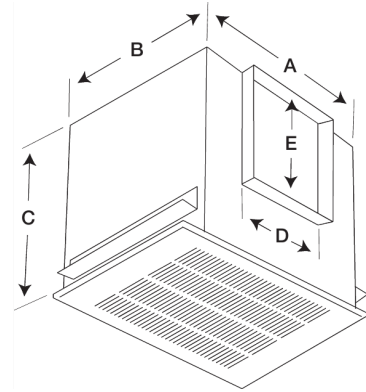


A	B	C	D	E
13.25 in	10.625 in	9 in	8 in	6 in

Certifications

AMCA Air & Sound
UL/cUL 507

Características de funcionamiento

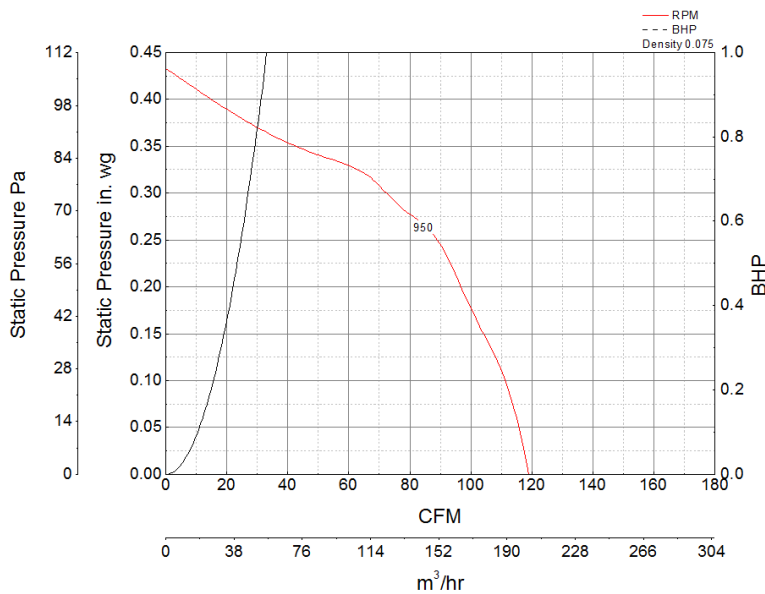

Características de Construcción

Drive Type	Direct Drive
Impeller Type	Centrifugal Wheel
Impeller Material	Polypropylene
Housing Material	Galvanized Steel
Includes	Backdraft damper Mounting brackets
Certifications	AMCA Air & Sound UL/cUL 507
Speed Controllable	Yes

Información del motor

Service Factor	1
Phase	1
Voltage	115
Hertz	60
RPM	950
Motor Insulation	A
Thermal Protection	Auto
Nominal Efficiency	24
Watts	18.5

Rendimiento de Aire y Sonido

Watts	Max Fan RPM	Min Fan RPM	Ps (in. wg)	0	0.125	0.25
19.4	950	760	PCM	130	115	98
			Sones	<0.3	<0.3	1.5



- Greenheck Fan Corporation certifies that the SP models shown herein are licensed to bear the AMCA seal.
- The ratings shown are based on tests and procedures performed in accordance with AMCA Publication 211 and AMCA Publication 311 and comply with the requirements of the AMCA Certified Ratings Program.
- The SP models are not AMCA certified with 50 hertz motors.

California Residents

 **WARNING**

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit www.P65Warnings.ca.gov