



SKU  
WD330-14X14


Job Name:  
Mark:  
Submitted By:  
Date: 03/08/2021

## Backdraft damper, vertical mount, Model WD-330, 14 In Sq, No Flange, Performance up to 2,500 ft/min



The WD-330 series dampers are designed to prevent reverse airflow in horizontal exhaust applications. The WD-330 features a pressure sensitive blade design that opens and remains open under low velocity conditions. The dampers are opened by air pressure differential and closed by gravity. Galvanized steel, flangeless frame.

- Width and height furnished approximately 0.125 in. under size

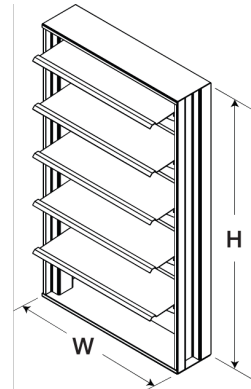

H	W
13.875 in	13.875 in

### Performance Characteristics

No Fan Curve Available.

### Construction Features

Frame Material	Galvanized Steel
Frame Gauge	18
Frame Type	No Flange
Blade Material	Roll formed aluminum
Blade Gauge	0.025

### California Residents

**⚠ WARNING**

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)