



SKU  
WD330-25X25


Nombre del Proyecto:  
Marca:  
Enviado por:  
Fecha: 11/12/2019

## Backdraft damper, vertical mount, Model WD-330, 25 In Sq, No Flange, Performance up to 2,500 ft/min



The WD-330 series dampers are designed to prevent reverse airflow in horizontal exhaust applications. The WD-330 features a pressure sensitive blade design that opens and remains open under low velocity conditions. The dampers are opened by air pressure differential and closed by gravity. Galvanized steel, flangeless frame.

- Width and height furnished approximately 0.125 in. under size

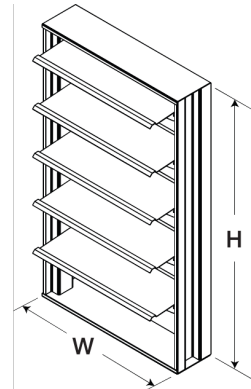

H	W
24.875 in	24.875 in

### Características de funcionamiento

No hay curva del ventilador disponible.

### Características de Construcción

Frame Material	Galvanized Steel
Frame Gauge	18
Frame Type	No Flange
Blade Material	Roll formed aluminum
Blade Gauge	0.025