



SKU  
WD410-8X8


Nombre del Proyecto:  
Marca:  
Enviado por:  
Fecha: 11/21/2019

## Backdraft damper, vertical or horizontal mount, Model WD-410, 8 In Sq, No Flange, Performance up to 2,500 ft/min



The WD-410 series are non-motorized backdraft dampers which may be mounted either vertically for intake air or mounted horizontally to allow vertical airflow down and prevent reverse airflow. The dampers are opened by air pressure differential and closed by springs.

- Width and height furnished approximately 0.125 in. under size

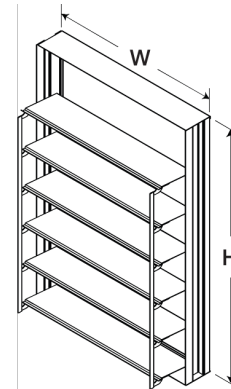

H	W
7.875 in	7.875 in

### Características de funcionamiento

No hay curva del ventilador disponible.

### Características de Construcción

Frame Material	Galvanized Steel
Frame Gauge	18
Frame Type	No Flange
Blade Material	Roll formed aluminum
Blade Gauge	0.025